


Slides 0201, Width 9.5 mm, to 49 kg, 3/4 Extension

Material:


Slide elements: Cold-rolled steel, zinc plated.
 Ball retainers: Cold-rolled, zinc-plated steel.
 Balls: Hardened steel.

Telescopic ball bearing slides for applications in the industrial and electronics sector.

- Can be mounted on both sides.
- Bracket mount for electrical cabinets on request.
- Service life 10,000 cycles.

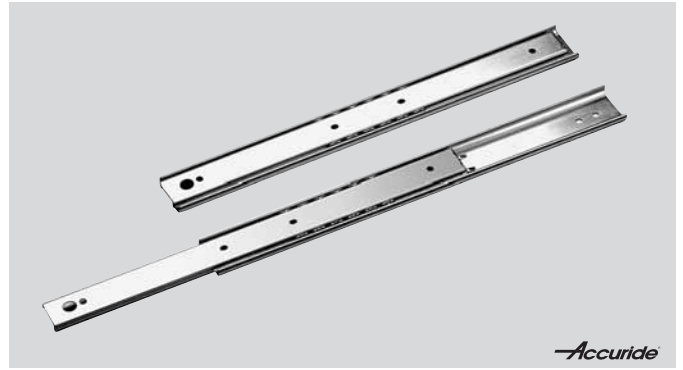

Ordering details: e.g.: Prod. No. 649 000 12, Slides 0201

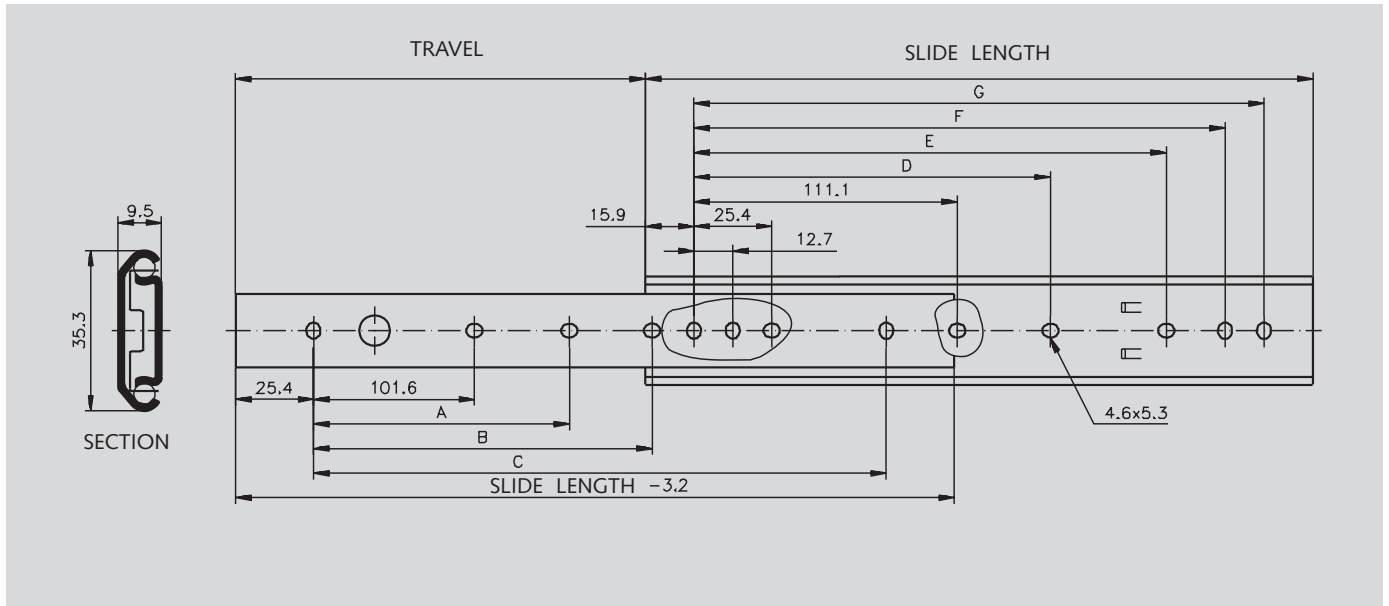

Product No. per Pair	Slide Length mm	Travel +/-3.2 mm	A mm	B mm	C mm	D mm	E mm	F mm	G mm	Load Rating per Pair kg	Weight per Pair kg
649 000 12	304.8	226.5	-	152.4	254.0	-	149.2	260.3	273.0	49	0.57
649 000 14	355.6	277.0	-	203.2	304.8	-	200.0	311.2	323.9	47	0.66
649 000 16	406.4	302.5	-	254.0	355.6	-	250.8	361.9	374.6	43	0.77
649 000 18	457.2	328.0	203.2	304.8	406.4	212.7	301.6	412.7	425.4	41	0.87
649 000 20	508.0	379.0	228.6	355.6	457.2	238.1	352.4	463.5	476.2	37	0.96
649 000 22	558.8	404.0	254.0	406.4	508.0	263.5	403.2	514.3	527.0	34	1.06
649 000 24	609.6	429.5	279.4	457.2	558.8	288.9	454.0	565.1	577.8	30	1.17
649 000 26	660.4	480.5	304.8	508.0	609.6	314.3	504.8	615.9	628.6	27	1.25
649 000 28	711.2	505.5	330.2	558.8	660.4	339.7	555.6	666.7	679.4	25	1.34

Note

Recommended mounts: M4 screw.
 Use all mounting positions to achieve the max. load rating.