

## Slides 2632, width 12.7 mm, up to 35 kg, compact profile, full extension


### Material:

Slide elements: Cold-rolled, bright zinc-plated steel.  
Ball retainers: Cold rolled, zinc-plated steel.  
Balls: Hardened steel.

Telescopic precision ball bearing slides for applications in the industrial and electronics sector.

- Lower slide height.
- Slot or side mounting possible.
- Hold-in in the closed position.
- Mounting slide and mounting material included.
- Very high service life 80.000 cycles.

Ordering Details: e.g.: Product No. 649 007 20, Slides 2632

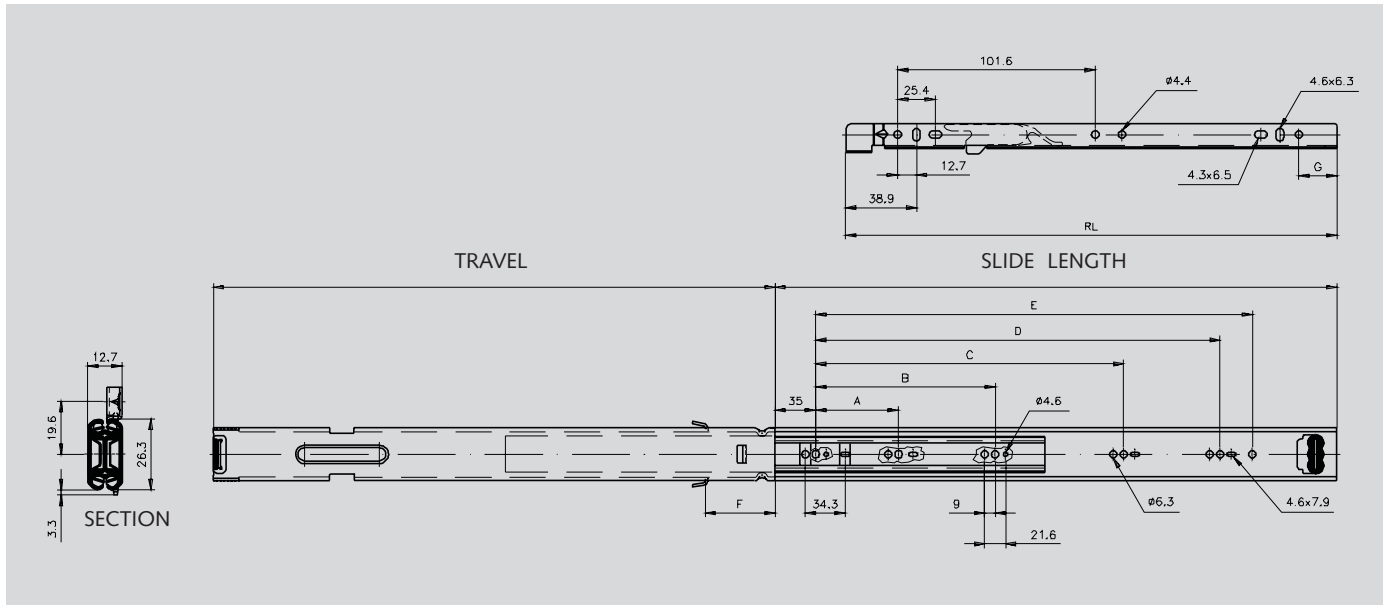

Product No. per pair	Slide length mm	Travel +/-3.2 mm	RL mm	A mm	B mm	C mm	D mm	E mm	F mm	G mm	Load Rating Pair kg	Weight Pair kg
649 007 20	203	203	165.1	128	-	-	-	-	37.6	12.7	16	0.60
649 007 25	254	254	165.1	128	-	-	-	-	88.4	12.7	23	0.76
649 007 30	305	305	273.8	128	224	-	-	-	35.1	26.7	32	0.91
649 007 35	356	356	273.8	128	224	-	-	-	85.9	26.7	34	1.03
649 007 40	407	407	337.8	128	224	320	-	-	72.6	26.7	32	1.19
649 007 45	457	457	337.8	128	224	352	-	-	123.4	26.7	29	1.32
649 007 50	508	508	433.8	128	224	416	-	-	78.2	26.7	29	1.49
649 007 55	559	559	433.8	128	224	352	448.1	480.1	129.0	26.7	27	1.62

### Note

Recommended fastening: M4/M6 screw.  
Head-Ø max. 7.8 mm, head height max. 2 mm.  
Use all mounting positions to achieve the max. load rating.

