


HTD Pulleys, Profile 5M for Taper Bushes

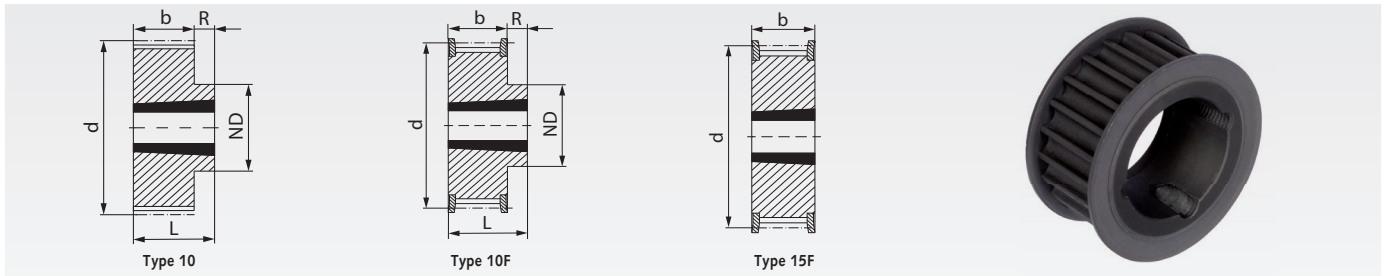

Material: Steel, phosphated.


Taper bushes see page 158.

Ordering Details: e.g.: Product No. 172 773 34, Taper Pulley, Pitch 5 mm, 12 Teeth, Timing Belt Width 15 mm

Profile 5M, Timing Belt Width 15 mm

Product No. 15mm	Number of teeth	Type	Outside-Ø		d mm	ND mm	b mm	L mm	R mm	Taper Bush Type page 158	Bore-Ø		Weight g
			Pulley mm	Flange mm							min. mm	max. mm	
172 773 34	34	15F	52,97	57	54,11	-	22	-	-	1008	9	25	200
172 773 36	36	15F	56,15	60	57,30	-	22	-	-	1108	9	28	250
172 773 38	38	15F	59,34	66	60,48	-	22	-	-	1108	9	28	300
172 773 40	40	15F	62,52	71	63,66	-	22	-	-	1108	9	28	350
172 773 44	44	15F	68,89	75	70,03	-	22	-	-	1108	9	28	400
172 773 48	48	10F	75,25	83	76,39	59	22	25	3	1210	10	32	460
172 773 56	56	10F	87,99	93	89,13	70	22	25	3	1210	10	32	600
172 773 64	64	10F	100,72	106	101,86	80	22	25	3	1210	10	32	800
172 773 72	72	10	113,45	-	114,59	92	22	25	3	1610	12	42	1200
172 773 80	80	10	126,18	-	127,32	92	22	25	3	1610	12	42	1760
172 773 90	90	10	142,10	-	143,24	92	22	25	3	1610	12	42	2320
172 773 94	112	10	177,11	-	178,25	110	20	32	12	2012	12	50	3710

HTD Pulleys Profile 5M

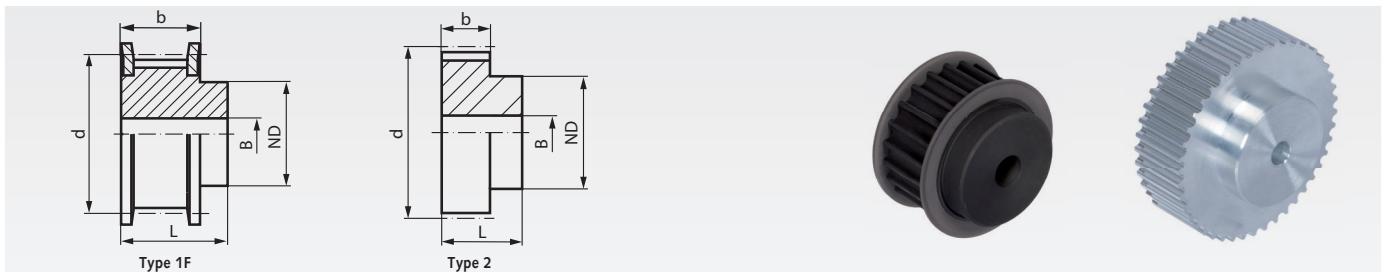

Material: Up to a Teeth Number of 72 steel, phosphated. From a Teeth Number of 44 aluminium similar to EN AW2017A.

Ordering Details: e.g.: Product No. 172 412 00, Pulleys, Pitch 5 mm, 12 Teeth, Timing Belt Width 25 mm

Profile 5M, Timing Belt Width 25 mm

Product No. 25mm	Number of teeth	Type	Outside-Ø		d mm	ND mm	b mm	L mm	Pilot Hole B mm	Custom Bore B max. mm	Weight g
			Pulley mm	Flange mm							
172 412 00	12	1F	17,96	23	19,10	12,5	30,5	36	6	8	50
172 414 00	14	1F	21,14	25	22,28	13,5	30,5	36	6	9	80
172 415 00	15	1F	22,73	28	23,87	16	30,5	36	6	10	90
172 416 00	16	1F	24,32	28	25,46	16,5	30,5	36	6	11	110
172 418 00	18	1F	27,51	32	28,65	20	30,5	36	6	13	130
172 420 00	20	1F	30,69	36	31,83	23	30,5	36	6	14	170
172 421 00	21	1F	32,28	38	33,42	24	30,5	38	6	14	200
172 422 00	22	1F	33,87	38	35,01	25,5	30,5	38	6	15	220
172 424 00	24	1F	37,06	42	38,20	27	30,5	38	6	16	260
172 426 00	26	1F	40,24	44	41,38	30	30,5	38	6	18	320
172 428 00	28	1F	43,42	48	44,56	30,5	30,5	38	6	18	370
172 430 00	30	1F	46,60	51	47,75	35	30,5	38	6	21	440
172 432 00	32	1F	49,79	54	50,93	38	30,5	38	8	23	480
172 436 00	36	1F	56,16	60	57,30	38	30,5	38	8	23	590
172 440 00	40	1F	62,52	71	63,66	38	30,5	38	8	23	750
172 444 00	44	2	68,89	-	70,03	38	30,5	40	8	23	310
172 448 00	48	2	75,25	-	76,39	38	30,5	40	8	23	370
172 460 00	60	2	94,35	-	95,49	50	30,5	40	8	30	600
172 472 00	72	2	113,45	-	114,59	50	30,5	40	8	30	850