


## HTD Pulleys, Profile 8M for Taper Bushes



**Material:** Up to a Teeth Number of 72 phosphated steel, from a Teeth Number of 80 phosphated grey cast iron GG25.

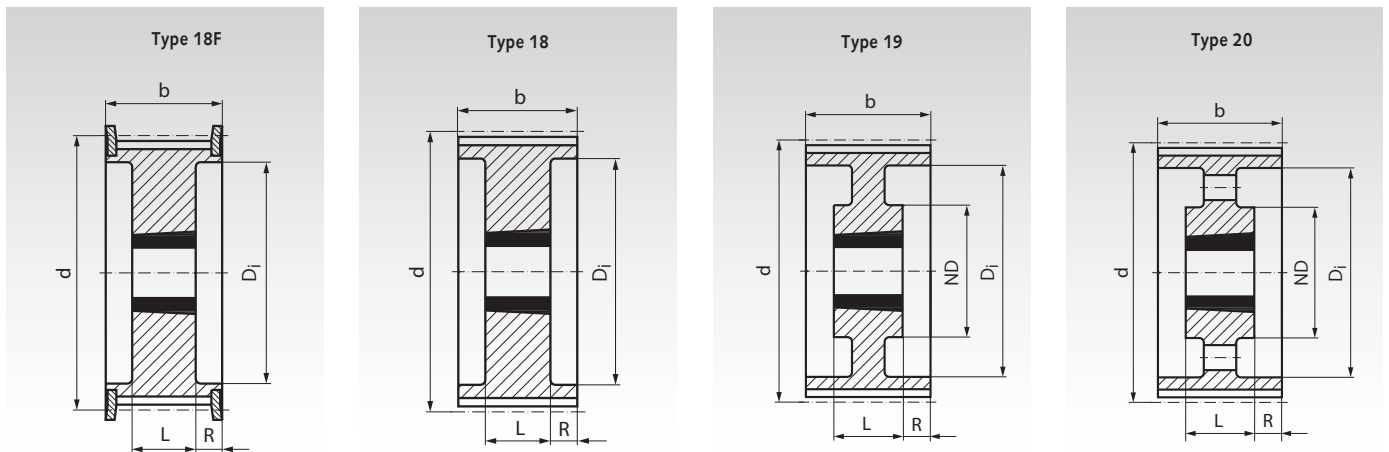

### Timing Belt Width 85 mm

Ordering Details: e.g.: Product No. 174 775 17, Taper-Pulley, 8M, 34 Teeth for Width 85 mm

Product No. 85mm	Number of teeth	Type	Outside Ø		d mm	ND mm	Di mm	b mm	L mm	R mm	Taper Bush Type Page 340	Bore Ø		Weight kg
			Pulley mm	Flange mm								min. mm	max. mm	
174 775 17	34	18F	85,22	91	86,58	-	65	95	38	28,5	1615	12	42	1,43
174 775 18	36	18F	90,30	97	91,67	-	68	95	38	28,5	1615	12	42	1,87
174 775 19	38	18F	95,39	102	96,77	-	72	95	38	28,5	1615	12	42	2,20
174 775 20	40	18F	100,49	106	101,86	-	80	95	32	31,5	2012	12	50	1,80
174 775 22	44	18F	110,67	120	112,05	-	86	95	32	31,5	2012	12	50	2,30
174 775 24	48	18F	120,86	128	122,23	-	97	95	45	25	2517	15	65	2,66
174 775 28	56	18F	141,23	150	142,60	-	116	95	45	25	2517	15	65	4,45
174 775 32	64	18F	161,60	168	162,97	-	136	95	45	25	2517	15	65	6,20
174 775 36	72	18F	181,97	192	183,35	-	150	95	51	22	3020	20	75	8,00
174 775 40	80	18	202,35	-	203,72	-	180	95	51	22	3020	20	75	10,00
174 775 45	90	18	227,81	-	229,18	-	204	95	51	22	3020	20	75	10,80
174 775 56	112	19	283,83	-	285,21	170	254	95	51	22	3020	20	75	15,00
174 775 72	144	19	365,32	-	366,69	198	336	95	65	15	3525	35	90	20,00
174 775 84	168	20	426,44	-	427,81	198	395	95	65	15	3525	35	90	22,00
174 775 96	192	20	487,55	-	488,92	198	455	95	65	15	3525	35	90	26,00

### Taper Clamping Bushes see page 340

These customary conical bushes are used for easy and fast mounting of driving elements in Taper version. They can be used with and without key.

The bushes are available with various outer dimensions. For every outside measure there are bushes with many different bores available. This mounting method is cost-efficient and fast, and suitable for rather high torques.

