
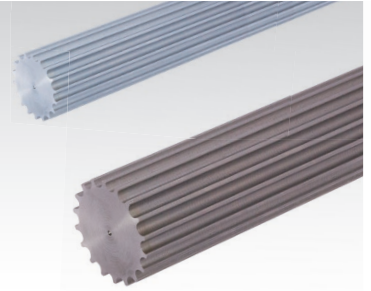


Timing Bars, for Timing Belts Profile HTD

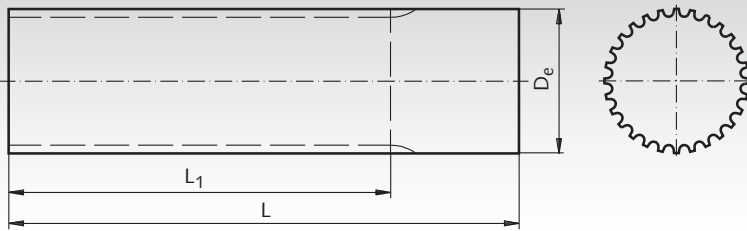


Material: HTD 3M and 5M: Aluminium similar to EN AW2017A.
HTD 8M: Steel.

Ordering Details: e.g.: Product No. 170 909 00,
Timing Bar HTD 3M, No. of Teeth 9

Profile 3M						Profile 5M						Profile 8M					
Product No.	Number of teeth	De mm	L1 mm	L mm	Weigth kg	Product No.	Number of teeth	De mm	L1 mm	L mm	Weigth kg	Product No.	Number of teeth	De mm	L1 mm	L mm	Weigth kg
170 909 00	9	7,83	75	100	0,01	172 912 00	12	17,96	160	160	0,08	174 915 00	15	36,83	200	200	1,23
170 910 00	10	8,79	75	100	0,02	172 913 00	13	19,55	160	160	0,10	174 916 00	16	39,37	200	200	1,49
170 911 00	11	9,74	75	100	0,02	172 914 00	14	21,14	175	200	0,16	174 917 00	17	41,92	200	200	1,76
170 912 00	12	10,70	100	125	0,03	172 915 00	15	22,73	175	200	0,19	174 918 00	18	44,47	200	200	2,03
170 913 00	13	11,65	100	125	0,03	172 916 00	16	24,32	175	200	0,21	174 919 00	19	47,01	200	200	2,30
170 914 00	14	12,61	100	125	0,04	172 917 00	17	25,92	175	200	0,24	174 920 00	20	49,56	200	200	2,57
170 915 00	15	13,56	100	125	0,04	172 918 00	18	27,51	200	200	0,27	174 921 00	21	52,11	200	200	2,88
170 916 00	16	14,52	125	155	0,06	172 919 00	19	29,10	200	200	0,31	174 922 00	22	54,65	200	200	3,18
170 917 00	17	15,47	125	155	0,07	172 920 00	20	30,69	200	200	0,35	174 923 00	23	57,20	200	200	3,52
170 918 00	18	16,43	125	155	0,08	172 921 00	21	32,28	200	200	0,39	174 924 00	24	59,75	200	200	3,86
170 919 00	19	17,38	125	155	0,09	172 922 00	22	33,87	200	200	0,43	174 925 00	25	62,29	200	200	4,23
170 920 00	20	18,34	150	165	0,11	172 923 00	23	35,47	200	200	0,48	174 926 00	26	64,84	200	200	4,60
170 921 00	21	19,25	150	165	0,12	172 924 00	24	37,06	200	200	0,52	174 928 00	28	69,93	200	200	5,40
170 922 00	22	20,25	150	165	0,13	172 925 00	25	38,85	200	200	0,57	174 930 00	30	75,02	200	200	6,27
170 923 00	23	21,20	150	165	0,15	172 926 00	26	40,24	200	200	0,62	174 932 00	32	80,12	200	200	7,20
170 924 00	24	22,16	150	165	0,16	172 927 00	27	41,83	200	200	0,67	174 934 00	34	85,21	200	200	8,20
170 925 00	25	23,11	150	165	0,17	172 928 00	28	43,42	200	200	0,73	174 935 00	35	87,76	200	200	8,71
170 926 00	26	24,07	150	165	0,19	172 930 00	30	46,61	200	200	0,84	174 936 00	36	90,30	200	200	9,26
170 927 00	27	25,02	150	165	0,21	172 932 00	32	49,79	200	200	0,97	174 938 00	38	95,40	200	200	10,39
170 928 00	28	25,98	150	165	0,22	172 934 00	34	52,97	200	200	1,11	174 940 00	40	100,49	200	200	11,58
170 929 00	29	26,93	150	165	0,24	172 936 00	36	56,16	200	200	1,25	174 944 00	44	110,88	200	200	14,16
170 930 00	30	27,89	175	183	0,29	172 938 00	38	59,34	200	200	1,40	174 948 00	48	120,86	200	200	16,99
170 931 00	31	28,84	175	183	0,31	172 940 00	40	62,52	200	200	1,55						
170 932 00	32	29,80	175	183	0,33	172 942 00	42	65,71	200	200	1,73						
170 933 00	33	30,75	175	183	0,35	172 944 00	44	68,89	200	200	1,90						
170 934 00	34	31,71	175	183	0,37	172 945 00	45	70,48	200	200	1,99						
170 935 00	35	32,66	175	183	0,39	172 948 00	48	75,25	200	200	2,27						
170 936 00	36	33,62	200	200	0,46	172 950 00	50	78,44	200	200	2,48						
170 937 00	37	34,57	200	200	0,48	172 960 00	60	94,35	200	200	3,60						
170 938 00	38	35,53	200	200	0,51	172 972 00	72	113,45	200	200	5,28						
170 939 00	39	36,48	200	200	0,54												
170 940 00	40	37,44	200	200	0,57												
170 942 00	42	39,34	200	200	0,63												
170 944 00	44	41,26	200	200	0,69												
170 945 00	45	42,21	200	200	0,73												
170 948 00	48	45,08	200	200	0,83												
170 950 00	50	46,99	200	200	0,91												
170 952 00	52	48,90	200	200	0,98												
170 954 00	54	50,81	200	200	1,06												
170 956 00	56	52,72	200	200	1,14												
170 960 00	60	56,54	200	200	1,32												
170 962 00	62	58,45	200	200	1,41												
170 964 00	64	60,36	200	200	1,54												
170 966 00	66	62,27	200	200	1,60												
170 968 00	68	64,18	200	200	1,70												
170 970 00	70	66,09	200	200	1,81												
170 972 00	72	67,99	200	200	1,92												



Flanges page 168

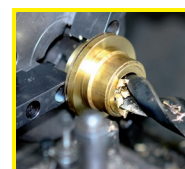

Reworking within
24h-service possible.
Custom made parts
on request.