


## Ball Valves Made from Brass, Exhausting, Full Bore

**Materials:** Housing: Brass, nickel plated,  
Ball seat: PTFE, O-ring seals: Viton.


Operating pressure: 0 to 45 bar.

Operating temperature: -20°C to +150°C.

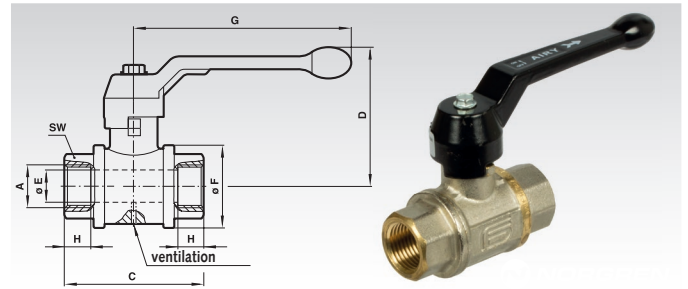

Ordering details e.g.: Product No. 865 131 28, Ball Valves Made from Brass, Exhausting, Full Bore, Internal Thread G<sup>1</sup>/<sub>4</sub>

Product No.	A	C	D	Ø E	Ø F	G	H	SW	Weight
		mm	mm	mm	mm	mm	mm	mm	g
865 131 28	G <sup>1</sup> / <sub>4</sub>	57	61	8	29	100	6,5	22	259
865 131 38	G <sup>3</sup> / <sub>8</sub>	54	61	10	29	100	8,5	22	245
865 131 48	G <sup>1</sup> / <sub>2</sub>	69	64	15	35	100	9,5	27	365
865 131 68	G <sup>3</sup> / <sub>4</sub>	77	76	20	45	120	10,5	33	619
865 131 88	G1	89	80	25	54	120	11,5	40	883

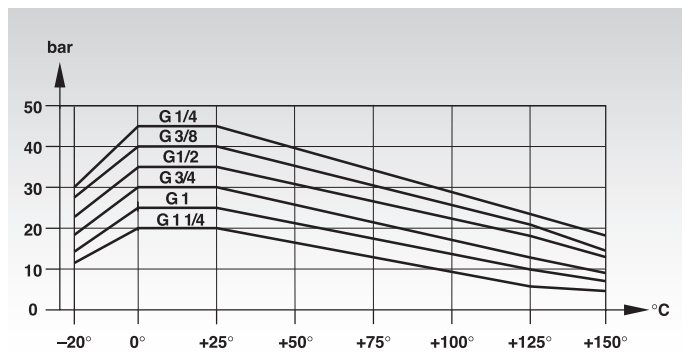


## Ball Valves Made from Brass, Full Bore

**Materials:** Housing: Brass, nickel plated.  
Seat: PTFE, O-ring seals: Viton.

Operating pressure: 0 to 45 bar.

Operating temperature: -20°C to +150°C.

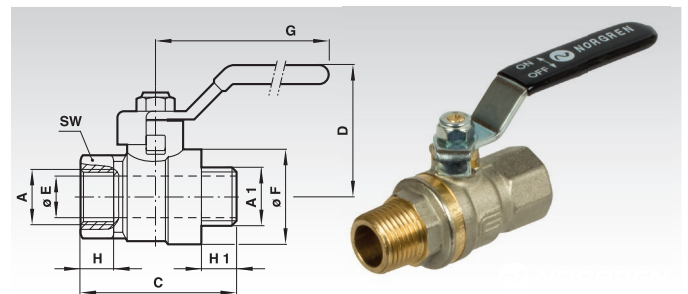

Ordering details e.g.: Product No. 865 022 28, Ball Valves made from Brass, Standard, Full Bore, External thread G<sup>1</sup>/<sub>4</sub>

Product No.	A	A1	C	D	Ø E	Ø F	G	SW	H	H1	Weight
			mm	mm	mm	mm	mm	mm	mm	mm	g
865 022 28	G <sup>1</sup> / <sub>4</sub>	G <sup>1</sup> / <sub>4</sub> A	50	36	8	23	85	18	6,5	6,5	128
865 022 38	G <sup>3</sup> / <sub>8</sub>	G <sup>3</sup> / <sub>8</sub> A	54	36	10	24	85	21	8,5	8,5	154
865 022 48	G <sup>1</sup> / <sub>2</sub>	G <sup>1</sup> / <sub>2</sub> A	65	40	15	30	85	25	9,5	9,5	212
865 022 68	G <sup>3</sup> / <sub>4</sub>	G <sup>3</sup> / <sub>4</sub> A	75	47	20	38	105	31	10,5	10,5	365
865 022 88	G1	G1A	86	51	25	46	105	38	11,5	11,5	545

