


Standard Pulleys, Inch Pitch ISO 5294

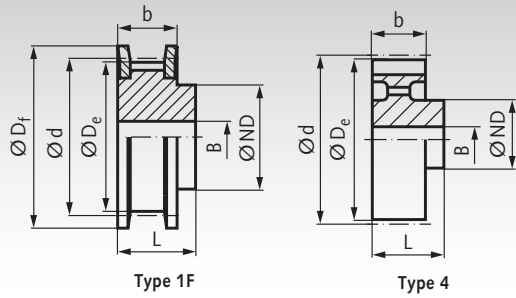


Material: Up to a Teeth Number of 48 phosphated steel, from a Teeth Number of 50 grey cast iron GG25. Pre-bored.

Ordering Details: e.g.: Product No. 182 310 00, Pulleys, Pitch $L = 3/8''$, 10 Teeth, Timing Belt Width 100, 2 Flanges

L 100: Pitch $3/8'' = 9.525 \text{ mm}$ for Timing Belt Width $1.00'' = 25.4 \text{ mm}$

Product No.	Number of teeth	Type	D_e mm	D_f mm	d mm	ND mm	b mm	L mm	B mm	Weight kg
182 310 00	10	1F	29,56	36	30,33	20	31,8	45	8	0,17
182 311 00	11	1F	32,59	38	33,35	24	31,8	45	8	0,20
182 312 00	12	1F	35,62	42	36,38	24	31,8	45	8	0,26
182 313 00	13	1F	38,65	44	39,41	28	31,8	45	8	0,31
182 314 00	14	1F	41,68	48	42,45	28	31,8	45	10	0,36
182 315 00	15	1F	44,72	51	45,48	34	31,8	45	10	0,44
182 316 00	16	1F	47,75	54	48,51	36	31,8	45	10	0,48
182 317 00	17	1F	50,78	57	51,54	36	31,8	45	10	0,55
182 318 00	18	1F	53,81	60	54,57	40	31,8	45	10	0,62
182 319 00	19	1F	56,84	63	57,61	40	31,8	45	10	0,69
182 320 00	20	1F	59,88	66	60,64	40	31,8	45	10	0,76
182 321 00	21	1F	62,91	71	63,67	45	31,8	45	10	0,86
182 322 00	22	1F	65,94	75	66,70	45	31,8	45	12	0,94
182 323 00	23	1F	68,97	79	69,73	55	31,8	45	12	1,11
182 324 00	24	1F	72,00	79	72,77	55	31,8	45	12	1,17
182 325 00	25	1F	75,04	83	75,80	58	31,8	45	12	1,29
182 326 00	26	1F	78,07	87	78,83	58	31,8	45	12	1,38
182 327 00	27	1F	81,10	87	81,86	58	31,8	45	12	1,46
182 328 00	28	1F	84,13	91	84,89	58	31,8	45	12	1,56
182 330 00	30	1F	90,20	97	90,96	70	31,8	45	12	1,89
182 332 00	32	1F	96,26	103	97,02	70	31,8	45	12	2,10
182 333 00	33	1F	99,29	106	100,05	70	31,8	45	12	2,21
182 334 00	34	1F	102,32	111	103,08	70	31,8	45	12	2,35
182 335 00	35	1F	105,35	111	106,12	70	31,8	45	12	2,44
182 336 00	36	1F	108,39	115	109,15	70	31,8	45	12	2,58
182 340 00	40	1F	120,51	127	121,28	70	31,8	45	12	3,12
182 344 00	44	1F	132,64	138	133,40	70	31,8	45	12	3,76
182 348 00	48	1F	144,77	152	145,53	70	31,8	45	12	4,33
182 350 00	50	4	150,83	-	151,60	70	31,8	45	14	2,21
182 356 00	56	4	169,02	-	169,79	70	31,8	45	14	2,44
182 360 00	60	4	181,15	-	181,81	75	31,8	45	14	2,79
182 372 00	72	4	217,53	-	218,30	75	31,8	45	14	3,16
182 384 00	84	4	253,92	-	254,68	75	31,8	45	14	3,73
182 387 00	96	4	290,30	-	291,06	75	31,8	45	14	4,25

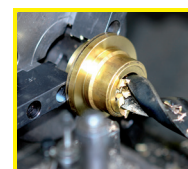

**Reworking within
24h-service possible.
Custom made parts
on request.**