


Standard Pulleys, Inch Pitch ISO 5294

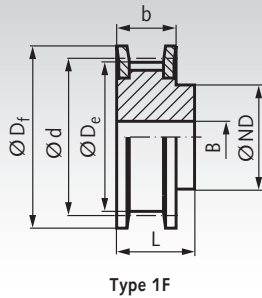

Type 1F



Material: Up to a Teeth Number of 40 phosphated steel, from a Teeth Number of 44 grey cast iron GG25 (on request). Pre-bored.


Ordering Details: e.g.: Product No. 184 214 00, Pulleys, Pitch H = 1/2", 14 Teeth, Timing Belt Width 150, 2 Flanges

H 150: Pitch 1/2" = 12.7 mm for Timing Belt Width 1.50" = 38.1 mm

Product No.	Number of teeth	Type	D _e mm	D _f mm	d mm	ND mm	b mm	L mm	B mm	Weight kg
184 214 00	14	1F	55,22	63	56,60	40	46	58	18	0,92
184 215 00	15	1F	59,27	66	60,64	45	46	58	18	1,08
184 216 00	16	1F	63,31	71	64,68	45	46	58	18	1,20
184 217 00	17	1F	67,35	75	68,72	45	46	58	18	1,24
184 218 00	18	1F	71,39	79	72,77	55	46	58	18	1,58
184 219 00	19	1F	75,44	83	76,81	60	46	58	18	1,77
184 220 00	20	1F	79,48	87	80,85	62	46	58	18	1,97
184 221 00	21	1F	83,52	91	84,89	65	46	58	18	2,08
184 222 00	22	1F	87,56	93	88,94	68	46	58	18	2,39
184 223 00	23	1F	91,61	97	92,98	72	46	58	18	2,50
184 224 00	24	1F	95,65	103	97,02	72	46	58	18	2,73
184 225 00	25	1F	99,69	106	101,06	72	46	58	18	3,05
184 226 00	26	1F	103,73	111	105,11	80	46	58	18	3,25
184 227 00	27	1F	107,78	115	109,15	80	46	58	18	3,86
184 228 00	28	1F	111,82	119	113,18	80	46	58	18	3,87
184 230 00	30	1F	119,90	127	121,28	80	46	58	18	4,37
184 232 00	32	1F	127,99	135	129,36	80	46	58	18	4,93
184 233 00	33	1F	132,03	138	133,40	80	46	58	18	5,14
184 234 00	34	1F	136,07	143	137,45	80	46	58	18	5,35
184 235 00	35	1F	140,12	148	141,49	80	46	58	18	5,73
184 236 00	36	1F	144,16	152	145,53	80	46	58	18	6,16
184 238 00	38	1F	152,24	158	153,62	80	46	58	18	6,83
184 240 00	40	1F	160,33	168	161,70	80	46	58	18	7,44

H 200: Pitch 1/2" = 12.7 mm for Timing Belt Width 2.00" = 50.8 mm

Product No.	Number of teeth	Type	D _e mm	D _f mm	d mm	ND mm	b mm	L mm	B mm	Weight kg
184 314 00	14	1F	55,22	63	56,60	40	58,7	70	18	1,14
184 315 00	15	1F	59,27	66	60,64	45	58,7	70	18	1,16
184 316 00	16	1F	63,31	71	64,68	45	58,7	70	18	1,49
184 317 00	17	1F	67,35	75	68,72	45	58,7	70	18	1,56
184 318 00	18	1F	71,39	79	72,77	55	58,7	70	18	1,93
184 319 00	19	1F	75,44	83	76,81	60	58,7	70	18	2,05
184 320 00	20	1F	79,48	87	80,85	62	58,7	70	18	2,42
184 321 00	21	1F	83,52	91	84,89	65	58,7	70	18	2,67
184 322 00	22	1F	87,56	93	88,94	68	58,7	70	18	2,94
184 323 00	23	1F	91,61	97	92,98	72	58,7	70	18	3,23
184 324 00	24	1F	95,65	103	97,02	72	58,7	70	18	3,49
184 325 00	25	1F	99,69	106	101,06	72	58,7	70	18	3,76
184 326 00	26	1F	103,73	111	105,11	80	58,7	70	18	4,15
184 327 00	27	1F	107,78	115	109,15	80	58,7	70	18	4,44
184 328 00	28	1F	111,82	119	113,18	80	58,7	70	18	4,77
184 330 00	30	1F	119,90	127	121,28	80	58,7	70	18	5,34
184 332 00	32	1F	127,99	135	129,36	80	58,7	70	18	6,16
184 333 00	33	1F	132,03	138	133,40	80	58,7	70	18	6,45
184 334 00	34	1F	136,07	143	137,45	80	58,7	70	18	6,73
184 335 00	35	1F	140,12	148	141,49	80	58,7	70	18	7,33
184 336 00	36	1F	144,16	152	145,53	80	58,7	70	18	7,74
184 338 00	38	1F	152,24	158	153,62	80	58,7	70	18	8,65
184 340 00	40	1F	160,33	168	161,70	80	58,7	70	18	9,46

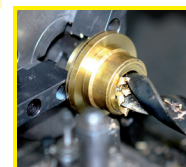

**Reworking within
24h-service possible.
Custom made parts
on request.**