


Splined Hubs - DIN ISO 14

Material: Steel C45Pb, from diameter 80 C45,
red brass (CuSn7Zn4Pb7-C).
Stainless steel 1.4305 (AISI 303).


© A/d up to size 18 x 22 = 0.15 mm, above 0.2 mm.

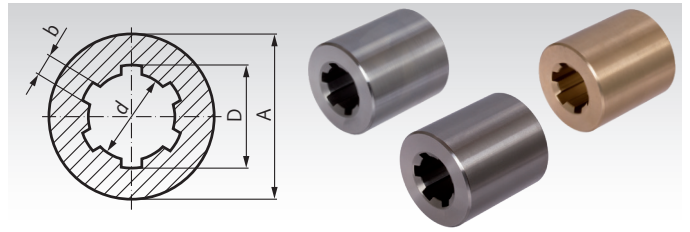

Ordering Details: e.g.: Product No. 648 302 00, Splined Hub DIN 14, KN 11 x 14

Product No. C45	Product No. Rg7	Product No. Stainless Steel	Profile Description mm	Number of keyways	Ø D ^{H11} mm	Ø d ^{H7} mm	b ^{D9} mm	DIN ISO 2768 m Ø A mm	Length mm	Weight Steel kg	Weight Rg7 kg
648 302 00	648 352 00	648 993 02	KN 11 x 14	6	14	11	3	20	40	0,06	0,08
648 304 00	648 354 00	648 993 04	KN 13 x 16	6	16	13	3,5	28	45	0,16	0,18
648 305 00	648 355 00	648 993 05	KN 16 x 20	6	20	16	4	32	45	0,20	0,22
648 301 00	648 351 00	648 993 01	KN 18 x 22	6	22	18	5	40	50	0,27	0,3
648 306 00	648 356 00	648 993 06	KN 21 x 25	6	25	21	5	40	55	0,36	0,42
648 303 00	648 353 00	648 993 03	KN 23 x 28	6	28	23	6	50	55	0,47	0,54
648 307 00	648 357 00	648 993 07	KN 26 x 32	6	32	26	6	52	60	0,70	0,78
648 309 00	648 359 00	648 993 09	KN 28 x 34	6	34	28	7	60	60	0,76	0,87
648 308 00	648 358 00	648 993 08	KN 32 x 38	8	38	32	6	60	60	0,88	1,00
648 312 00	648 362 00	648 993 12	KN 36 x 42	8	42	36	7	70	65	1,08	1,23
648 310 00	648 360 00	648 993 10	KN 42 x 48	8	48	42	8	65	70	0,94	1,10
648 311 00	648 361 00	648 993 11	KN 42 x 48	8	48	42	8	80	70	1,88	2,16
648 314 00	648 364 00	648 993 14	KN 46 x 54	8	54	46	9	80	90	2,25	2,49

Collars
page 570

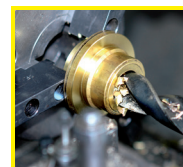

**Reworking within
24h-service possible.
Custom made parts
on request.**