


Cabinet "U" Handles 425

Material: Version CR: Steel, chrome-plated.
Washers zinc die-cast, nickel-plated.
Version NI: Stainless steel 1.4305 (AISI 303),
blasted, matt finish. Washers stainless steel
1.4305 (AISI 303).

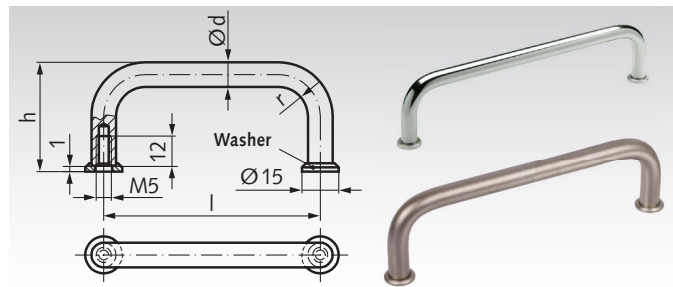

Supplied with two washers. These discs guarantee perfect positioning even with large bores in the cabinet. The washers are loosely packed.




Ordering Details: e.g.: Product No. 666 612 00, Cabinet "U" Handle 425, CR, 88 mm

Product No. Version CR	Product No. Version NI	Length l mm	d mm	h mm	r mm	Weight g
666 612 00	666 996 12	88	10	42	12	89
666 614 00	666 996 14	100	10	42	12	96
666 616 00	666 996 16	120	10	42	12	108
666 619 00	666 996 19	180	10	42	12	148
666 621 00	666 996 21	200	10	42	12	160
666 623 00	666 996 23	235	10	42	12	181

Folding Handles Made

Material: Version CR: Steel, chrome-plated.
Version NI: 1.4305 (AISI 303), blasted, matt finish.

Mainly used in applications where the handle should not stick out, or where sticking out should be kept to a minimum. The handle is locked in both end positions by a spring-loaded pressure pin. Hexagon nuts and washers are included in the delivery.

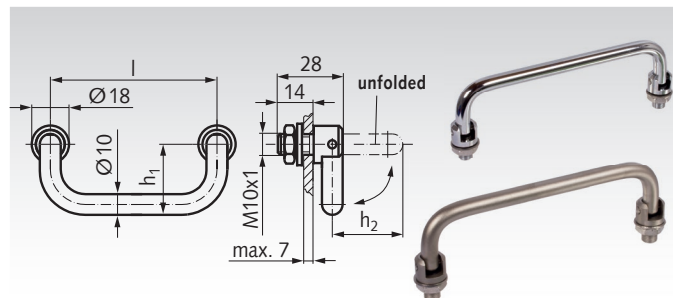


Ordering Details: e.g.: Product No. 666 680 00, Folding Handle, Steel, Chrome Plated

Product No. Version CR	Product No. Version NI	Length l mm	h ₁ mm	h ₂ mm	Weight g
666 680 00	666 996 80	100	34	44	150
666 682 00	666 996 82	120	34	44	161
666 688 00	666 996 88	180	34	44	195

Folding Handle with Recessed Tray 425.4

Material:
Folding handle made from steel, chrome plated. Tray: Zinc die-cast, plastic coated, black.

Used in applications where the folded handle must not stick out, or where the sticking out must be max. 3 mm. In addition, screws M4 are sufficient for mounting the handle on the housing. Handle and folding mechanism are made from chrome-plated steel and the tray is made from zinc die-cast. This gives the folding handle additional strength (supplied as complete assembly).

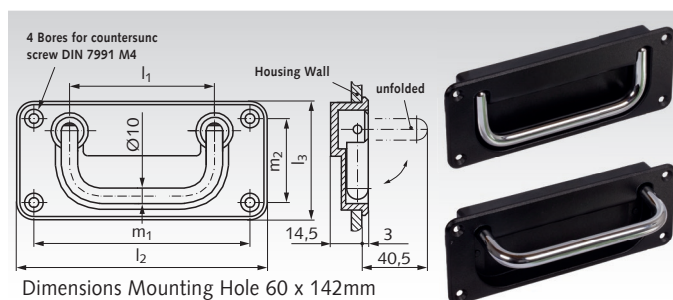

Ordering Details: e.g.: Product No. 666 550 00, Folding Handle with Recessed Tray

Product-No.	Lenght l ₁ mm	l ₂ mm	l ₃ mm	m ₁ mm	m ₂ mm	Weight g
666 550 00	120	170	65	154	49	402