


## Otočné rukoväte DIN 98 ST

**Materiál:** Oceľ, pozinkovaná.

**Verzia E** = so závitovým čapom a imbus hlavou.

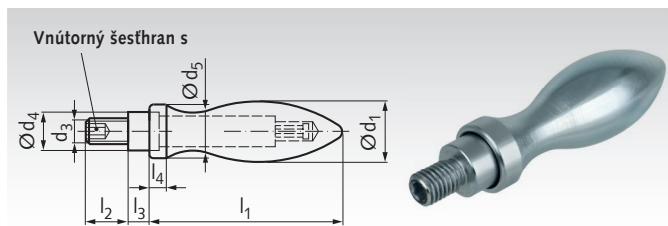

Informácie potrebné na objednanie: napr.: Produkt č. 663 116 00, Rukoväť DIN 98 ST, Verzia E 16 mm


Produkt č. Verzia E	d <sub>1</sub> mm	d <sub>3</sub> mm	d <sub>4</sub> <sup>h13</sup> mm	d <sub>5</sub> mm	l <sub>1</sub> mm	l <sub>2</sub> mm	l <sub>3</sub> mm	l <sub>4</sub> mm	s mm	Hmotnosť g
663 116 00	16	M6	10	14	49	11	5,5	5	3	55
663 120 00	20	M8	13	18	61	13	6	6	4	104
663 125 00	25	M10	16	21	75	14	8	6,5	5	187
663 132 00	32	M12	20	26	95	21	10,5	8	6	387
663 136 00	36	M16	22	29	106	26	11	9	8	541

## Otočné rukoväte DIN 98 TH

**Materiál:** Plast Termoplast (Polyamid), čierny, matný.

**Verzia E** = so závitovým čapom a imbus hlavou.

Čap: Oceľ, pozinkovaná.

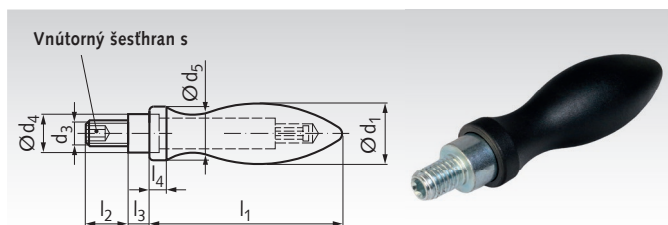

Informácie potrebné na objednanie: napr.: Produkt č. 663 216 00, Rukoväť DIN 98 TH, Verzia E 16 mm


Produkt č. Verzia E	d <sub>1</sub> mm	d <sub>3</sub> mm	d <sub>4</sub> <sup>h13</sup> mm	d <sub>5</sub> mm	l <sub>1</sub> mm	l <sub>2</sub> mm	l <sub>3</sub> mm	l <sub>4</sub> mm	s mm	Hmotnosť g
663 216 00	16	M6	10	14	49	11	5,5	5	3	21
663 220 00	20	M8	13	18	61	13	6	6	4	45
663 225 00	25	M10	16	21	75	14	8	6,5	5	71
663 232 00	32	M12	20	26	95	21	10,5	8	6	144

## Otočné rukoväte DIN 98 AL

**Material:** Leštený hliník.

**Verzia E** = so závitovým čapom a imbus hlavou.

Čap: Oceľ, pozinkovaná.

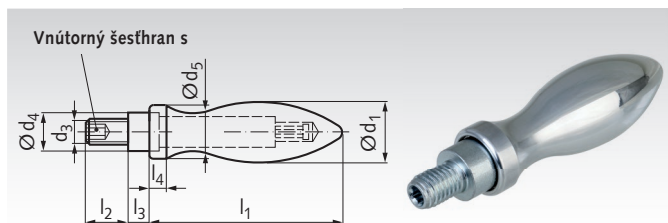

Informácie potrebné na objednanie: napr.: Produkt č. 663 316 00, Rukoväť DIN 98 AL, Verzia E 16 mm

Produkt č. Verzia E	d <sub>1</sub> mm	d <sub>3</sub> mm	d <sub>4</sub> <sup>h13</sup> mm	d <sub>5</sub> mm	l <sub>1</sub> mm	l <sub>2</sub> mm	l <sub>3</sub> mm	l <sub>4</sub> mm	s mm	Hmotnosť g
663 316 00	16	M6	10	14	49	11	5,5	5	3	20
663 320 00	20	M8	13	18	61	13	6	6	4	35
663 325 00	25	M10	16	21	75	14	8	6,5	5	85
663 332 00	32	M12	20	26	95	21	10,5	8	6	150
663 336 00	36	M16	22	29	106	26	11	9	8	210