
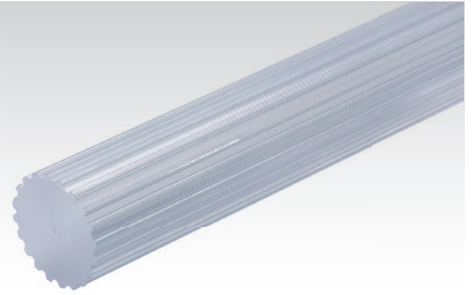


## Zahnwellen Profil T, Aluminium

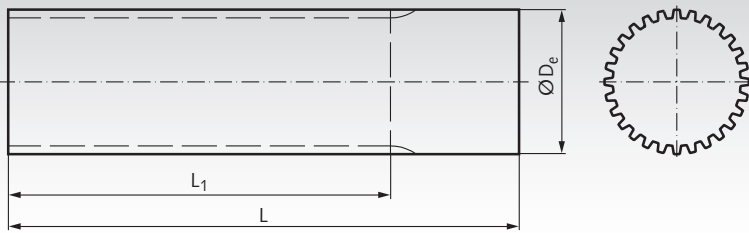

Werkstoff: Aluminium ähnlich EN AW2017A.

Bestellangaben: z.B.: Art.-Nr. 160 910 10, Zahnwellen T 2,5, Zähnezahl 10

Andere Ausführungen und Werkstoffe auf Anfrage.

### Profil T 2,5

| Artikel-Nr. | Zähnezahl | De mm | L1 mm | L mm | Gewicht kg |
|-------------|-----------|-------|-------|------|------------|
| 160 910 00  | 10        | 7,46  | 50    | 75   | 0,01       |
| 160 911 00  | 11        | 8,25  | 50    | 75   | 0,01       |
| 160 912 00  | 12        | 9,05  | 50    | 75   | 0,01       |
| 160 913 00  | 13        | 9,85  | 50    | 75   | 0,02       |
| 160 914 00  | 14        | 10,64 | 50    | 75   | 0,02       |
| 160 915 00  | 15        | 11,44 | 75    | 75   | 0,02       |
| 160 916 00  | 16        | 12,23 | 75    | 75   | 0,02       |
| 160 917 00  | 17        | 13,03 | 75    | 75   | 0,03       |
| 160 918 00  | 18        | 13,82 | 75    | 75   | 0,03       |
| 160 919 00  | 19        | 14,62 | 120   | 120  | 0,05       |
| 160 920 00  | 20        | 15,42 | 120   | 120  | 0,05       |
| 160 921 00  | 21        | 16,21 | 120   | 120  | 0,06       |
| 160 922 00  | 22        | 17,01 | 140   | 140  | 0,08       |
| 160 923 00  | 23        | 17,80 | 140   | 140  | 0,09       |
| 160 924 00  | 24        | 18,60 | 140   | 140  | 0,09       |
| 160 925 00  | 25        | 19,39 | 140   | 140  | 0,11       |
| 160 926 00  | 26        | 20,19 | 140   | 140  | 0,12       |
| 160 927 00  | 27        | 20,99 | 140   | 140  | 0,13       |
| 160 928 00  | 28        | 21,78 | 140   | 140  | 0,14       |
| 160 929 00  | 29        | 22,58 | 140   | 140  | 0,15       |
| 160 930 00  | 30        | 23,37 | 140   | 140  | 0,15       |
| 160 932 00  | 32        | 24,96 | 140   | 140  | 0,18       |
| 160 934 00  | 34        | 26,56 | 140   | 140  | 0,21       |
| 160 935 00  | 35        | 27,35 | 140   | 140  | 0,21       |
| 160 936 00  | 36        | 28,15 | 140   | 140  | 0,22       |
| 160 938 00  | 38        | 29,74 | 140   | 140  | 0,26       |
| 160 940 00  | 40        | 31,33 | 140   | 140  | 0,27       |
| 160 942 00  | 42        | 32,92 | 140   | 140  | 0,32       |
| 160 944 00  | 44        | 34,51 | 140   | 140  | 0,33       |
| 160 945 00  | 45        | 35,31 | 140   | 140  | 0,37       |
| 160 948 00  | 48        | 37,70 | 140   | 140  | 0,40       |
| 160 950 00  | 50        | 39,29 | 160   | 160  | 0,52       |
| 160 960 00  | 60        | 47,25 | 160   | 160  | 0,72       |
| 160 965 00  | 65        | 51,23 | 160   | 160  | 0,87       |
| 160 970 00  | 70        | 55,20 | 160   | 160  | 1,05       |
| 160 972 00  | 72        | 56,80 | 160   | 160  | 1,11       |
| 160 980 00  | 80        | 63,16 | 160   | 160  | 1,30       |
| 160 984 00  | 84        | 66,35 | 160   | 160  | 1,50       |
| 160 990 00  | 90        | 71,12 | 160   | 160  | 1,75       |
| 160 996 00  | 96        | 75,89 | 160   | 160  | 2,00       |
| 160 999 00  | 100       | 79,08 | 160   | 160  | 2,18       |

### Profil T 5


| Artikel-Nr. | Zähnezahl | De mm  | L1 mm | L mm | Gewicht kg |
|-------------|-----------|--------|-------|------|------------|
| 162 910 00  | 10        | 15,08  | 140   | 140  | 0,06       |
| 162 911 00  | 11        | 16,67  | 140   | 140  | 0,07       |
| 162 912 00  | 12        | 18,26  | 140   | 140  | 0,09       |
| 162 913 00  | 13        | 19,85  | 140   | 140  | 0,10       |
| 162 914 00  | 14        | 21,44  | 140   | 140  | 0,12       |
| 162 915 00  | 15        | 23,03  | 140   | 140  | 0,14       |
| 162 916 00  | 16        | 24,62  | 140   | 140  | 0,16       |
| 162 917 00  | 17        | 26,22  | 140   | 140  | 0,19       |
| 162 918 00  | 18        | 27,81  | 140   | 140  | 0,21       |
| 162 919 00  | 19        | 29,40  | 140   | 140  | 0,24       |
| 162 920 00  | 20        | 30,99  | 160   | 160  | 0,31       |
| 162 921 00  | 21        | 32,58  | 160   | 160  | 0,33       |
| 162 922 00  | 22        | 34,17  | 160   | 160  | 0,36       |
| 162 923 00  | 23        | 35,77  | 160   | 160  | 0,39       |
| 162 924 00  | 24        | 37,36  | 160   | 160  | 0,43       |
| 162 925 00  | 25        | 38,95  | 160   | 160  | 0,47       |
| 162 926 00  | 26        | 40,54  | 160   | 160  | 0,51       |
| 162 927 00  | 27        | 42,13  | 160   | 160  | 0,55       |
| 162 928 00  | 28        | 43,72  | 160   | 160  | 0,60       |
| 162 929 00  | 29        | 45,31  | 160   | 160  | 0,65       |
| 162 930 00  | 30        | 46,91  | 160   | 160  | 0,70       |
| 162 932 00  | 32        | 50,09  | 160   | 160  | 0,80       |
| 162 934 00  | 34        | 53,27  | 160   | 160  | 0,91       |
| 162 935 00  | 35        | 54,86  | 160   | 160  | 0,98       |
| 162 936 00  | 36        | 56,46  | 160   | 160  | 1,02       |
| 162 937 00  | 37        | 58,05  | 160   | 160  | 1,08       |
| 162 938 00  | 38        | 59,64  | 160   | 160  | 1,14       |
| 162 940 00  | 40        | 62,82  | 160   | 160  | 1,27       |
| 162 942 00  | 42        | 66,01  | 160   | 160  | 1,41       |
| 162 944 00  | 44        | 69,19  | 160   | 160  | 1,55       |
| 162 945 00  | 45        | 70,78  | 160   | 160  | 1,63       |
| 162 946 00  | 46        | 72,37  | 160   | 160  | 1,69       |
| 162 948 00  | 48        | 75,55  | 160   | 160  | 1,85       |
| 162 950 00  | 50        | 78,74  | 160   | 160  | 2,02       |
| 162 960 00  | 60        | 94,65  | 160   | 160  | 2,95       |
| 162 965 00  | 65        | 102,61 | 160   | 160  | 3,50       |
| 162 972 00  | 72        | 113,75 | 160   | 160  | 4,28       |
| 162 980 00  | 80        | 126,48 | 160   | 160  | 5,39       |
| 162 984 00  | 84        | 132,85 | 160   | 160  | 6,00       |
| 162 990 00  | 90        | 142,40 | 160   | 160  | 6,76       |
| 162 996 00  | 96        | 151,95 | 160   | 160  | 7,40       |
| 162 999 00  | 100       | 158,31 | 160   | 160  | 8,34       |

### Profil T 10

| Artikel-Nr. | Zähnezahl | De mm  | L1 mm | L mm | Gewicht kg |
|-------------|-----------|--------|-------|------|------------|
| 164 910 00  | 10        | 29,97  | 140   | 140  | 0,22       |
| 164 911 00  | 11        | 33,15  | 140   | 140  | 0,29       |
| 164 912 00  | 12        | 36,34  | 140   | 140  | 0,34       |
| 164 913 00  | 13        | 39,52  | 140   | 140  | 0,42       |
| 164 914 00  | 14        | 42,70  | 160   | 160  | 0,55       |
| 164 915 00  | 15        | 45,89  | 160   | 160  | 0,64       |
| 164 916 00  | 16        | 49,07  | 160   | 160  | 0,74       |
| 164 917 00  | 17        | 52,25  | 160   | 160  | 0,85       |
| 164 918 00  | 18        | 55,44  | 160   | 160  | 0,96       |
| 164 919 00  | 19        | 58,62  | 160   | 160  | 1,07       |
| 164 920 00  | 20        | 61,80  | 160   | 160  | 1,20       |
| 164 921 00  | 21        | 64,99  | 160   | 160  | 1,29       |
| 164 922 00  | 22        | 68,17  | 160   | 160  | 1,43       |
| 164 923 00  | 23        | 71,35  | 160   | 160  | 1,58       |
| 164 924 00  | 24        | 74,53  | 160   | 160  | 1,73       |
| 164 925 00  | 25        | 77,72  | 160   | 160  | 1,85       |
| 164 926 00  | 26        | 80,90  | 160   | 160  | 2,05       |
| 164 927 00  | 27        | 84,08  | 160   | 160  | 2,25       |
| 164 928 00  | 28        | 87,27  | 160   | 160  | 2,39       |
| 164 929 00  | 29        | 90,45  | 160   | 160  | 2,55       |
| 164 930 00  | 30        | 93,63  | 160   | 160  | 2,76       |
| 164 932 00  | 32        | 100,00 | 160   | 160  | 3,18       |
| 164 934 00  | 34        | 106,37 | 160   | 160  | 3,61       |
| 164 936 00  | 36        | 112,73 | 160   | 160  | 4,06       |
| 164 938 00  | 38        | 119,10 | 160   | 160  | 4,62       |
| 164 940 00  | 40        | 125,46 | 160   | 160  | 5,13       |
| 164 942 00  | 42        | 131,83 | 160   | 160  | 5,50       |
| 164 944 00  | 44        | 138,20 | 160   | 160  | 6,00       |
| 164 945 00  | 45        | 141,38 | 160   | 160  | 6,50       |
| 164 948 00  | 48        | 150,93 | 160   | 160  | 7,39       |
| 164 960 00  | 60        | 189,13 | 160   | 160  | 11,76      |
| 164 972 00  | 72        | 227,32 | 160   | 160  | 17,03      |



Bordscheiben Seite 198

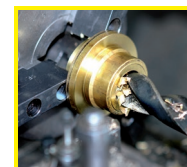

Fertigbearbeitung im  
24-Stunden-Service möglich.  
Sonderanfertigungen und  
Zeichnungsteile auf Anfrage.