


Double-Strand plate wheels ZRL, ISO 06 B-2

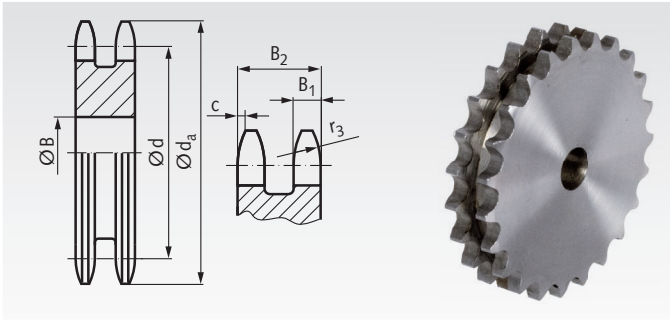


Material: Low-carbon steel, not hardable.
Pre-bored.

Ordering Details: e.g.: Product No. 12121100, ZRL, ISO 06 B-2, 11 Teeth

ISO 06 B-2, Pitch 3/8 x 7/32"

$B_1 = 5.2 \text{ mm}$, $B_2 = 15.4 \text{ mm}$ $c = 1.0 \text{ mm}$, $r_3 = 10 \text{ mm}$

Product No. ZRL	Number of teeth	d_a mm	d mm	B mm	Weight g	Product No. ZRL	Number of teeth	d_a mm	d mm	B mm	Weight g
121 208 00	8	28,3	24,89	6	34	121 250 00	50	155,9	151,69	16	1997
121 209 00	9	31,4	27,85	8	42	121 251 00	51	158,9	154,72	16	2081
121 210 00	10	34,4	30,82	8	55	121 252 00	52	162,0	157,75	16	2168
121 211 00	11	37,5	33,81	10	66	121 253 00	53	165,0	160,78	16	2253
121 212 00	12	40,5	36,80	10	83	121 254 00	54	168,0	163,82	20	2331
121 213 00	13	43,6	39,80	10	103	121 255 00	55	171,1	166,85	16	2436
121 214 00	14	46,6	42,80	10	123	121 256 00	56	174,1	169,88	16	2539
121 215 00	15	49,7	45,81	10	145	121 257 00	57	177,1	172,91	20	2619
121 216 00	16	52,7	48,82	12	164	121 258 00	58	180,2	175,94	16	2730
121 217 00	17	55,8	51,84	12	190	121 260 00	60	186,2	182,00	16	2928
121 218 00	18	58,8	54,85	12	217	121 262 00	62	192,3	188,06	20	3120
121 219 00	19	61,8	57,87	12	246	121 264 00	64	198,4	194,12	20	3332
121 220 00	20	64,9	60,89	12	277	121 265 00	65	201,4	197,15	20	3441
121 221 00	21	67,9	63,91	12	310	121 268 00	68	210,5	206,24	20	3777
121 223 00	23	74,0	69,95	12	379	121 270 00	70	216,6	212,30	20	4010
121 224 00	24	77,0	72,97	12	417	121 272 00	72	222,6	218,37	20	4249
121 225 00	25	80,1	76,00	12	457	121 275 00	75	231,7	227,46	20	4622
121 226 00	26	83,1	79,02	12	498	121 276 00	76	234,8	230,49	25	4729
121 227 00	27	86,1	82,05	12	540	121 278 00	78	240,8	236,55	20	5010
121 228 00	28	89,2	85,07	16	574	121 280 00	80	246,9	242,61	20	5277
121 229 00	29	92,2	88,10	12	631	121 281 00	85	262,0	257,77	20	5990
121 230 00	30	95,2	91,12	16	672	121 282 00	90	277,2	272,93	20	6733
121 231 00	31	98,3	94,15	14	729	121 283 00	95	292,4	288,08	25	7498
121 232 00	32	101,3	97,18	16	774	121 284 00	100	307,5	303,24	20	8347
121 233 00	33	104,3	100,20	14	833	121 285 00	110	337,9	333,55	20	10134
121 234 00	34	107,4	103,23	14	889	121 288 00	114	350,0	345,68	25	10892
121 235 00	35	110,4	106,26	16	940	121 289 00	125	383,3	379,03	20	13158
121 236 00	36	113,4	109,29	14	1004						
121 237 00	37	116,5	112,32	14	1064						
121 238 00	38	119,5	115,34	16	1120						
121 239 00	39	122,5	118,37	14	1189						
121 240 00	40	125,6	121,40	16	1249						
121 241 00	41	128,6	124,43	16	1316						
121 242 00	42	131,6	127,46	16	1385						
121 243 00	43	134,7	130,49	16	1455						
121 244 00	44	137,7	133,52	16	1528						
121 245 00	45	140,7	136,55	20	1588						
121 246 00	46	143,8	139,58	16	1677						
121 247 00	47	146,8	142,61	16	1755						
121 248 00	48	149,8	145,64	20	1820						
121 249 00	49	152,9	148,67	16	1915						

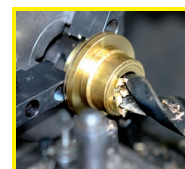

**Reworking within
24h-service possible.
Custom made parts
on request.**