


## V-Belt Pulleys for Taper Bushes, Profile Z, SPZ and XPZ (10), 3 Grooves

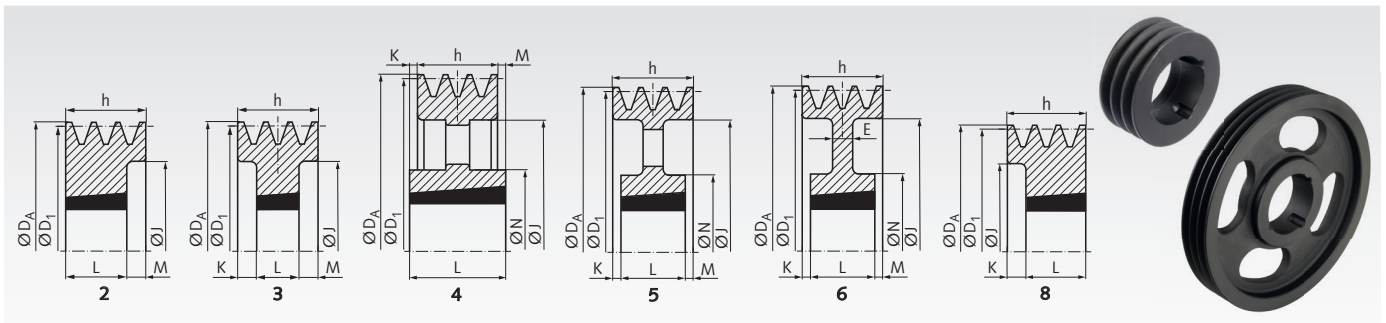

**Material:** cast iron EN-GJL-250, phosphated.

V-belt pulleys for taper bushes, for easy and fast mounting. The taper bush has to be ordered separately.


Regarding DIN 2211, DIN 2217 and ISO 4183, matching to classical V-belts DIN 2215 and narrow V-belts DIN 7753-1 / ISO 4184. Also suitable for V-belts 3V/9N according to ARPM/MPTA. The nominal diameter  $D_1$  is the datum diameter.

**Ordering Details:** e.g.: Product No. MAE 151-Z-3-63, V-Belt Pulley for Taper Clamping Bush, Profile Z, 3 Grooves, Nominal Diameter 63 mm

Product No. Profile Z, SPZ, XPZ	No. of Grooves	Nominal Ø		Design	fitting Bush No.	Bore mm	E mm	h mm	J mm	K mm	L mm	M mm	N mm	Weight kg
		$D_1$ mm	$D_A$ mm											
MAE 151-Z-3-63	3	63	67	8	1108	9 - 28	-	40	40	18	22	-	-	0,5
MAE 151-Z-3-67	3	67	71	8	1108	9 - 28	-	40	42	18	22	-	-	0,5
MAE 151-Z-3-71	3	71	75	8	1108	9 - 28	-	40	42	18	22	-	-	0,7
MAE 151-Z-3-75	3	75	79	8	1210	10 - 32	-	40	51	15	25	-	-	0,6
MAE 151-Z-3-80	3	80	84	8	1210	10 - 32	-	40	51	15	25	-	-	0,5
MAE 151-Z-3-85	3	85	89	8	1610	12 - 42	-	40	60	15	25	-	-	0,8
MAE 151-Z-3-90	3	90	94	8	1610	12 - 42	-	40	61	15	25	-	-	0,85
MAE 151-Z-3-95	3	95	99	8	1610	12 - 42	-	40	66	15	25	-	-	1,2
MAE 151-Z-3-100	3	100	104	8	1610	12 - 42	-	40	71	15	25	-	-	1,2
MAE 151-Z-3-106	3	106	110	8	1610	12 - 42	-	40	76	15	25	-	-	1,2
MAE 151-Z-3-112	3	112	116	8	2012	12 - 50	-	40	83	8	32	-	-	1,4
MAE 151-Z-3-118	3	118	122	8	2012	12 - 50	-	40	90	8	32	-	-	1,5
MAE 151-Z-3-125	3	125	129	2	2012	12 - 50	-	40	96	-	32	8	-	2,0
MAE 151-Z-3-132	3	132	136	2	2012	12 - 50	-	40	103	-	32	8	-	2,0
MAE 151-Z-3-140	3	140	144	2	2012	12 - 50	-	40	111	-	32	8	-	2,7
MAE 151-Z-3-150	3	150	154	2	2012	12 - 50	-	40	121	-	32	8	-	3,0
MAE 151-Z-3-160	3	160	164	2	2012	12 - 50	-	40	131	-	32	8	-	3,8
MAE 151-Z-3-170	3	170	174	3	2012	12 - 50	-	40	141	4	32	4	-	4,5
MAE 151-Z-3-180	3	180	184	6	2012	12 - 50	7	40	151	0	32	8	106	3,4
MAE 151-Z-3-190	3	190	194	6	2012	12 - 50	10	40	161	4	32	4	112	3,5
MAE 151-Z-3-200	3	200	204	6	2012	12 - 50	10	40	171	4	32	4	112	4,0
MAE 151-Z-3-224	3	224	228	6	2012	12 - 50	12	40	195	4	32	4	112	5,0
MAE 151-Z-3-250	3	250	254	5	2012	12 - 50	-	40	221	4	32	4	112	5,0
MAE 151-Z-3-280	3	280	284	4	2517	15 - 65	-	40	251	2,5	45	2,5	124	7,5
MAE 151-Z-3-315	3	315	319	4	2517	15 - 65	-	40	286	2,5	45	2,5	124	8,2
MAE 151-Z-3-355	3	355	359	4	2517	15 - 65	-	40	326	2,5	45	2,5	124	11,0
MAE 151-Z-3-400	3	400	404	4	2517	15 - 65	-	40	371	2,5	45	2,5	124	11,2
MAE 151-Z-3-450	3	450	454	4	2517	15 - 65	-	40	421	2,5	45	2,5	124	13,1
MAE 151-Z-3-500	3	500	504	4	2517	15 - 65	-	40	471	2,5	45	2,5	124	15,0
MAE 151-Z-3-630	3	630	634	4	3020	20 - 75	-	40	601	5,5	51	5,5	150	18,0
MAE 151-Z-3-800	3	800	804	4	3020	20 - 75	-	40	771	5,5	51	5,5	146	41,5


### Taper Bushes

The bushes are available with various outer dimensions. For every outside measure there are bushes with many different bores available. They can be used with and without key.

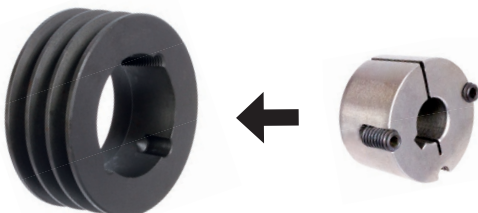

### Mounting

Videos are available on our homepage and on YouTube. The instructions are available as a PDF file in the online shop and on paper in the scope of delivery of the bush.

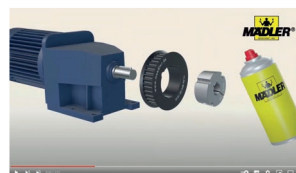

- D** [www.maedler.de](http://www.maedler.de)
- A** [www.maedler.at](http://www.maedler.at)
- CH** [www.maedler.ch](http://www.maedler.ch)