


V-Belt Pulleys for Taper Bushes, Profile Z, SPZ and XPZ (10), 5 Grooves

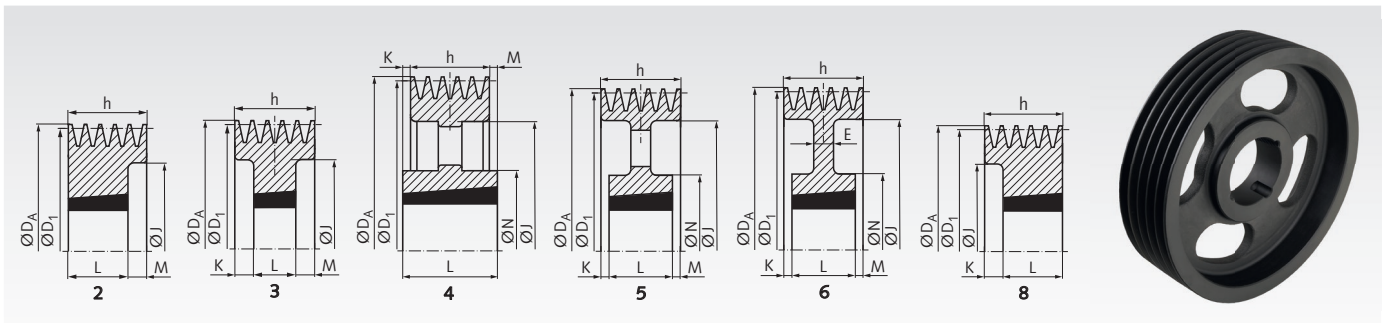

Material: cast iron EN-GJL-250, phosphated.

V-belt pulleys for taper bushes, for easy and fast mounting. The taper bush has to be ordered separately.


Regarding DIN 2211, DIN 2217 and ISO 4183, matching to classical V-belts DIN 2215 and narrow V-belts DIN 7753-1 / ISO 4184. Also suitable for V-belts 3V/9N according to ARPM/MPTA. The nominal diameter D_1 is the datum diameter.

Ordering Details: e.g.: Product No. MAE 151-Z-5-85, V-Belt Pulley for Taper Clamping Bush, Profile Z, 5 Grooves, Nominal Diameter 85 mm

Product No. Profile Z, SPZ, XPZ	No. of Grooves	Nominal Ø		Design	fitting Bush No.	Bore mm	E mm	h mm	J mm	K mm	L mm	M mm	N mm	Weight kg
		D_1 mm	D_A mm											
MAE 151-Z-5-85	5	85	89	8	1610	12 - 42	-	64	60	39	25	-	-	1,20
MAE 151-Z-5-90	5	90	94	8	1610	12 - 42	-	64	61	39	25	-	-	1,50
MAE 151-Z-5-95	5	95	99	8	1610	12 - 42	-	64	66	39	25	-	-	1,45
MAE 151-Z-5-100	5	100	104	8	2012	12 - 50	-	64	71	32	32	-	-	1,50
MAE 151-Z-5-106	5	106	110	8	2012	12 - 50	-	64	76	32	32	-	-	0,70
MAE 151-Z-5-112	5	112	116	8	2012	12 - 50	-	64	83	32	32	-	-	4,00
MAE 151-Z-5-118	5	118	122	8	2012	12 - 50	-	64	90	32	32	-	-	2,30
MAE 151-Z-5-125	5	125	129	8	2012	12 - 50	-	64	96	32	32	-	-	3,00
MAE 151-Z-5-132	5	132	136	8	2517	15 - 65	-	64	103	19	45	19	-	3,00
MAE 151-Z-5-140	5	140	144	2	2517	15 - 65	-	64	111	-	45	19	-	3,00
MAE 151-Z-5-150	5	150	154	2	2517	15 - 65	-	64	121	-	45	19	-	4,20
MAE 151-Z-5-160	5	160	164	2	2517	15 - 65	-	64	131	-	45	19	-	5,00
MAE 151-Z-5-170	5	170	174	2	2517	15 - 65	-	64	141	-	45	19	-	6,00
MAE 151-Z-5-180	5	180	184	2	2517	15 - 65	-	64	151	-	45	19	-	7,50
MAE 151-Z-5-190	5	190	194	3	2517	15 - 65	-	64	161	9,5	45	9,5	-	8,00
MAE 151-Z-5-200	5	200	204	3	2517	15 - 65	-	64	171	9,5	45	9,5	-	6,20
MAE 151-Z-5-224	5	224	228	6	2517	15 - 65	20	64	195	9,5	45	9,5	124	9,00
MAE 151-Z-5-250	5	250	254	6	2517	15 - 65	16	64	221	9,5	45	9,5	124	9,00
MAE 151-Z-5-280	5	280	284	6	2517	15 - 65	15	64	251	9,5	45	9,5	124	10,5
MAE 151-Z-5-315	5	315	319	5	2517	15 - 65	-	64	286	9,5	45	9,5	124	11,0
MAE 151-Z-5-355	5	355	359	5	2517	15 - 65	-	64	326	9,5	45	9,5	124	13,8
MAE 151-Z-5-400	5	400	404	5	3020	20 - 75	-	64	371	6,5	51	6,5	146	14,5
MAE 151-Z-5-450	5	450	454	5	3020	20 - 75	-	64	421	6,5	51	6,5	146	20,0
MAE 151-Z-5-500	5	500	504	4	3030	30 - 75	-	64	471	6	76	6	146	23,5
MAE 151-Z-5-630	5	630	634	4	3030	30 - 75	-	64	601	6	76	6	146	29,5
MAE 151-Z-5-800	5	800	804	4	3535	30 - 90	-	64	771	12,5	89	12,5	178	44,0


Taper Bushes

The bushes are available with various outer dimensions. For every outside measure there are bushes with many different bores available. They can be used with and without key.

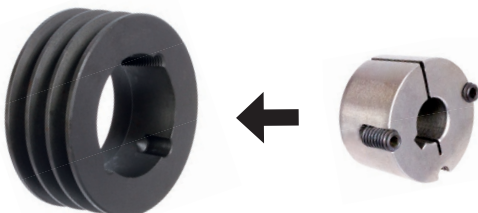

Mounting

Videos are available on our homepage and on YouTube. The instructions are available as a PDF file in the online shop and on paper in the scope of delivery of the bush.

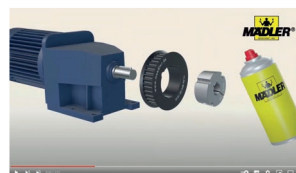

- D** www.maedler.de
- A** www.maedler.at
- CH** www.maedler.ch