


V-Belt Pulleys for Taper Bushes, Profile B, SPB and XPB (17), 2 Grooves

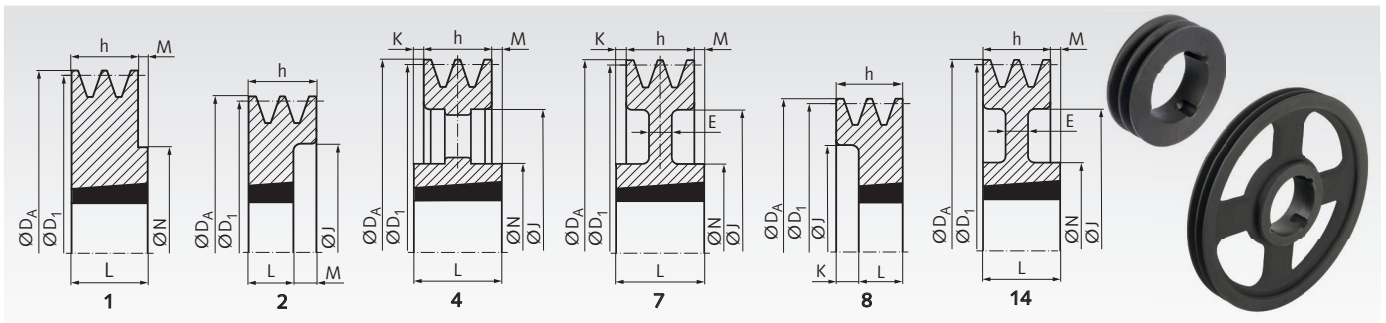

Material: cast iron EN-GJL-250, phosphated.

V-belt pulleys for taper bushes, for easy and fast mounting. The taper bush has to be ordered separately.

Regarding DIN 2211, DIN 2217 and ISO 4183, matching to classical V-belts DIN 2215 and narrow V-belts DIN 7753-1 / ISO 4184. Also suitable for V-belts 5V/15N according to ARPM/MPTA. The nominal diameter D_1 is the datum diameter.

Ordering Details: e.g.: Product No. MAE 151-B-2-100, V-Belt Pulley for Taper Clamping Bush, Profile B, 2 Grooves, Nominal Diameter 100 mm


Product No. Profile B, SPB, XPB	No. of Grooves	Nominal Ø		Design	fitting Bush No.	Bore mm	E mm	h mm	J mm	K mm	L mm	M mm	N mm	Weight kg
		D_1 mm	D_A mm											
MAE 151-B-2-100	2	100 ¹⁾	107	8	1610	12 - 42	-	44	62	19	25	-	-	1,3
MAE 151-B-2-106	2	106 ¹⁾	113	8	1610	12 - 42	-	44	67	19	25	-	-	1,5
MAE 151-B-2-112	2	112 ²⁾	119	8	1610	12 - 42	-	44	72	19	25	-	-	1,75
MAE 151-B-2-118	2	118 ²⁾	125	2	1610	12 - 42	-	44	78	-	25	19	-	1,8
MAE 151-B-2-125	2	125 ²⁾	132	2	2012	12 - 50	-	44	82	-	32	12	-	2,0
MAE 151-B-2-132	2	132 ²⁾	139	2	2012	12 - 50	-	44	89	-	32	12	-	2,35
MAE 151-B-2-140	2	140	147	2	2012	12 - 50	-	44	97	-	32	12	-	2,7
MAE 151-B-2-150	2	150	157	2	2012	12 - 50	-	44	107	-	32	12	-	3,3
MAE 151-B-2-160	2	160	167	2	2012	12 - 50	-	44	117	-	32	12	-	4,0
MAE 151-B-2-170	2	170	177	2	2012	12 - 50	-	44	127	-	32	12	-	4,5
MAE 151-B-2-180	2	180	187	1	2517	15 - 65	-	44	-	-	45	1	120	5,5
MAE 151-B-2-190	2	190	197	1	2517	15 - 65	-	44	-	-	45	1	120	6,44
MAE 151-B-2-200	2	200	207	14	2517	15 - 65	-	44	160	-	45	1	120	5,36
MAE 151-B-2-212	2	212	219	14	2517	15 - 65	20	44	169	-	45	1	117	7,0
MAE 151-B-2-224	2	224	231	14	2517	15 - 65	15	44	181	-	45	1	117	6,69
MAE 151-B-2-236	2	236	243	14	2517	15 - 65	15	44	193	-	45	1	117	8,4
MAE 151-B-2-250	2	250	257	14	2517	15 - 65	20	44	207	-	45	1	125	8,5
MAE 151-B-2-280	2	280	287	14	2517	15 - 65	20	44	237	-	45	1	125	8,0
MAE 151-B-2-300	2	300	307	14	2517	15 - 65	20	44	257	-	45	1	125	5,85
MAE 151-B-2-315	2	315	322	14	2517	15 - 65	20	44	272	-	45	1	125	13,2
MAE 151-B-2-335	2	335	342	14	2517	15 - 65	20	44	292	-	45	1	125	14
MAE 151-B-2-355	2	355	362	7	3020	20 - 75	15	44	312	3,5	51	3,5	144	15,9
MAE 151-B-2-400	2	400	407	4	3020	20 - 75	-	44	357	3,5	51	3,5	150	16
MAE 151-B-2-450	2	450	457	4	3020	20 - 75	-	44	407	3,5	51	3,5	150	17
MAE 151-B-2-500	2	500	507	4	3020	20 - 75	-	44	457	3,5	51	3,5	150	19
MAE 151-B-2-560	2	560	567	4	3030	30 - 75	-	44	517	16	76	16	150	24
MAE 151-B-2-630	2	630	637	4	3030	30 - 75	-	44	587	16	76	16	150	25

1) Not for V-belts SPB, XPB and 5V/15N.

2) Not for V-belts SPB and 5V/15N.


Taper Bushes

The bushes are available with various outer dimensions. For every outside measure there are bushes with many different bores available. They can be used with and without key.

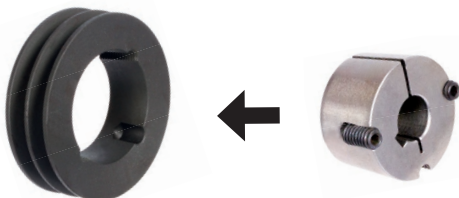

Mounting

Videos are available on our homepage and on YouTube. The instructions are available as a PDF file in the online shop and on paper in the scope of delivery of the bush.

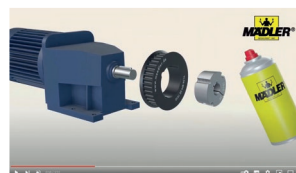

D www.maedler.de
A www.maedler.at
CH www.maedler.ch