


V-Belt Pulleys for Taper Bushes, Profile B, SPB and XPB (17), 5 Grooves

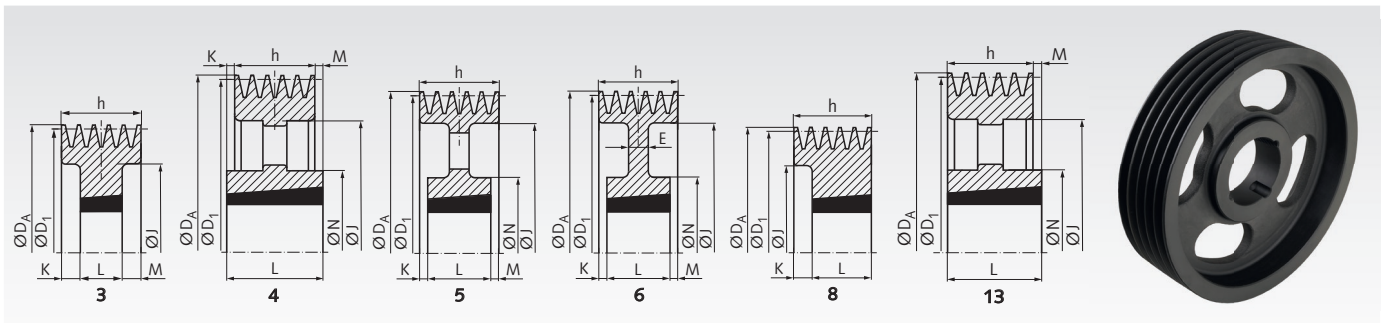

Material: cast iron EN-GJL-250, phosphated.

V-belt pulleys for taper bushes, for easy and fast mounting. The taper bush has to be ordered separately.

Regarding DIN 2211, DIN 2217 and ISO 4183, matching to classical V-belts DIN 2215 and narrow V-belts DIN 7753-1 / ISO 4184. Also suitable for V-belts 5V/15N according to ARPM/MPTA. The nominal diameter D_1 is the datum diameter.


Ordering Details: e.g.: Product No. MAE 151-B-5-125, V-Belt Pulley for Taper Clamping Bush, Profile B, 5 Grooves, Nominal Diameter 125 mm

Product No. Profile B, SPB, XPB	No. of Grooves	Nominal Ø		Design	fitting Bush No.	Bore mm	E mm	h mm	J mm	K mm	L mm	M mm	N mm	Weight kg
		D_1 mm	D_A mm											
MAE 151-B-5-125	5	125 ¹⁾	132	8	2012	12 - 50	-	101	87	69	32	-	-	3,6
MAE 151-B-5-132	5	132 ¹⁾	139	8	2517	15 - 65	-	101	94	56	45	-	-	3,8
MAE 151-B-5-140	5	140	147	3	2517	15 - 65	-	101	97	28	45	28	-	4,4
MAE 151-B-5-150	5	150	157	3	2517	15 - 65	-	101	107	28	45	28	-	5,5
MAE 151-B-5-160	5	160	167	3	2517	15 - 65	-	101	117	28	45	28	-	6,7
MAE 151-B-5-170	5	170	177	3	3020	20 - 75	-	101	127	25	51	25	-	6,35
MAE 151-B-5-180	5	180	187	3	3020	20 - 75	-	101	137	25	51	25	-	7,7
MAE 151-B-5-190	5	190	197	3	3020	20 - 75	-	101	147	25	51	25	-	9,0
MAE 151-B-5-200	5	200	207	3	3020	20 - 75	-	101	157	25	51	25	-	10,4
MAE 151-B-5-212	5	212	219	3	3020	20 - 75	-	101	169	25	51	25	-	11,9
MAE 151-B-5-224	5	224	231	3	3020	20 - 75	-	101	181	25	51	25	-	13,5
MAE 151-B-5-236	5	236	243	3	3535	30 - 90	-	101	193	6	89	6	-	19,1
MAE 151-B-5-250	5	250	257	3	3535	30 - 90	-	101	207	6	89	6	-	22,4
MAE 151-B-5-280	5	280	287	6	3535	30 - 90	25	101	237	6	89	6	175	20,5
MAE 151-B-5-300	5	300	307	6	3535	30 - 90	25	101	257	6	89	6	175	20,5
MAE 151-B-5-315	5	315	322	6	3535	30 - 90	25	101	272	6	89	6	175	23,3
MAE 151-B-5-335	5	335	342	6	3535	30 - 90	25	101	292	6	89	6	175	26,4
MAE 151-B-5-355	5	355	362	6	3535	30 - 90	17	101	312	6	89	6	175	27,0
MAE 151-B-5-400	5	400	407	5	3535	30 - 90	-	101	357	6	89	6	175	28,5
MAE 151-B-5-450	5	450	457	5	3535	30 - 90	-	101	407	-	89	12	175	34,0
MAE 151-B-5-500	5	500	507	5	3535	30 - 90	-	101	457	-	89	12	175	41,0
MAE 151-B-5-560	5	560	567	13	4040	40 - 100	-	101	517	-	102	1	210	51,0
MAE 151-B-5-630	5	630	637	13	4040	40 - 100	-	101	587	-	102	1	210	55,5
MAE 151-B-5-710	5	710	717	13	4040	40 - 100	-	101	664	-	102	1	210	65,20
MAE 151-B-5-800	5	800	807	13	4040	40 - 100	-	101	754	-	102	1	210	81,0
MAE 151-B-5-900	5	900	907	13	4040	40 - 100	-	101	854	-	102	1	210	98,0
MAE 151-B-5-1000	5	1000	1007	4	4545	55 - 110	-	101	954	6,5	114	6,5	242	125,0
MAE 151-B-5-1250	5	1250	1257	4	4545	55 - 110	-	101	1204	6,5	114	6,5	242	167,5

¹⁾ Not for V-belts SPB and 5V/15N.


Taper Bushes

The bushes are available with various outer dimensions. For every outside measure there are bushes with many different bores available. They can be used with and without key.

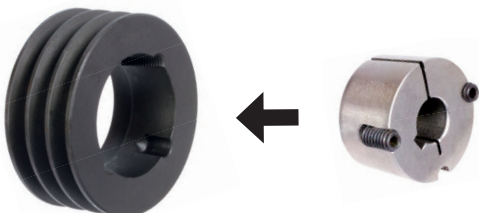

Mounting

Videos are available on our homepage and on YouTube. The instructions are available as a PDF file in the online shop and on paper in the scope of delivery of the bush.

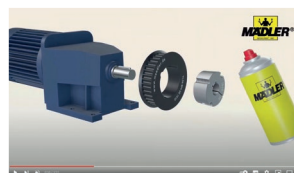

- D** www.maedler.de
- A** www.maedler.at
- CH** www.maedler.ch